

BAYONET CABLE

PRODUCT SPECIFICATIONS


PS-BC-01/01-060711



Bayonet cable is a plug & play Sundaya standart instalation cable that usually could be applied on Sundaya lightkit system with 2 bayonet plugs on the cable ends.

Available type in different length :

- # Bayonet cable 120
- # Bayonet cable 240
- # Bayonet cable 360
- # Bayonet cable 480

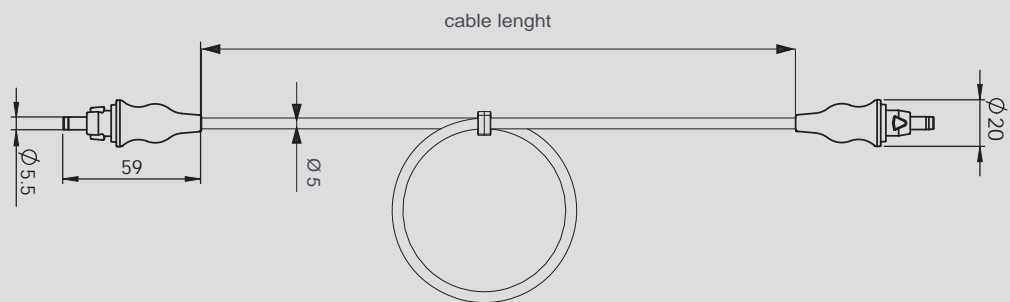

Electrical details

Rated Voltage	30 V
Rated Current	0,5 A
Withstand Voltage	AC 500 V (50 Hz) at 1 minute
Insulation Resistance	≥ 500 M Ohm
Contact Resistance	≤ 0,03 Ohm
Actuating Force	3 to 20 N

Mechanical details

Operating Temperature Range	-25 C to + 85 C
Colors	Black
Plug Material	PVC Rubber
Product Dimensions (Ø x L)	
Bayonet Cable 120	Ø 5 x 1200 mm
Bayonet Cable 240	Ø 5 x 2400 mm
Bayonet Cable 360	Ø 5 x 3600 mm
Bayonet Cable 480	Ø 5 x 4800 mm
Nett Product Weight	
Bayonet Cable 120	53 gr
Bayonet Cable 240	87 gr
Bayonet Cable 360	121 gr
Bayonet Cable 480	155 gr